

1U Adjustable Depth Heavy Duty Fixed / Vented Rack Mount Shelf - 175lbs / 80kg


ADJSHELFHD / ADJSHELFHDV

DE: Bedienungsanleitung - de.startech.com
 FR: Guide de l'utilisateur - fr.startech.com
 ES: Guía del usuario - es.startech.com
 IT: Guida per l'uso - it.startech.com
 NL: Gebruiksaanwijzing - nl.startech.com
 PT: Guia do usuário - pt.startech.com

Warning: To prevent bodily injury, please ensure that the rack is installed in a structurally sound environment with a level floor and that all hardware has been assembled securely, and checked for stability before loading equipment. When installing equipment into the rack, start from the bottom of the rack first and move upwards, keeping the heaviest equipment at the bottom to avoid a situation where the rack becomes top-heavy.

Packaging Contents

- 1 x Shelf Body
- 2 x Front Mounting Bracket
- 2 x Rear Mounting Bracket
- 8 x M5x12 Hex Screw

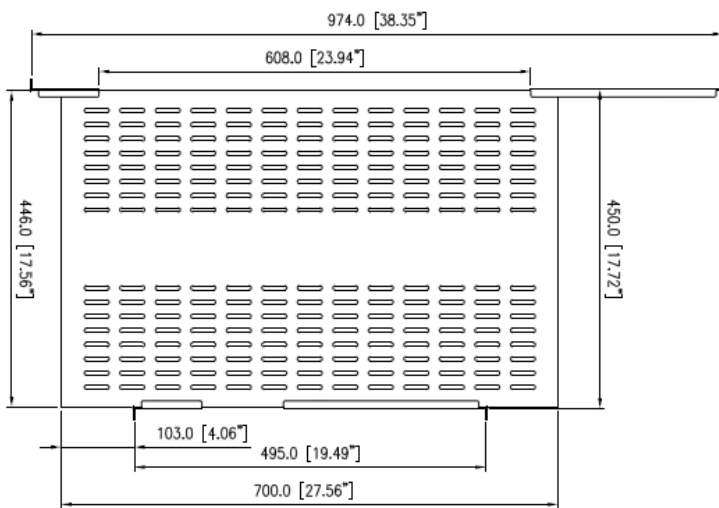

*ADJSHELFHD Shown



*ADJSHELFHDV Shown

Installation

1. Locate a suitable location in the rack/cabinet to mount the shelf - the shelf itself requires 1U of space.
2. If the rack uses square mounting holes, install cage nuts (not included) into the square mounting holes on the front posts of the rack.
3. Place the shelf into the rack and align the mounting points on the front brackets of the shelf with the mounting points on the rack (for example, cage nuts, if used).
4. Use the provided cabinet screws to secure the shelf to the rack. If you're not using cage nuts or M6 threaded rack posts, you should use the appropriate mounting hardware for the rack.
5. Make sure the screws are properly tightened and the shelf has no movement before attempting to place anything on the shelf. Be sure to observe the maximum weight capacity of the shelf.

Specifications

	ADJSHELFHD	ADJSHELFHDV
Description	1U Adjustable Depth Heavy Duty Fixed Rack Mount Shelf	1U Adjustable Depth Heavy Duty Vented Rack Mount Shelf
Material	SPCC (1.0mm thick)	SPCC1.2mm thick)
Color	Black	
Max Weight Capacity	175lbs/80kg	250lbs/113kg
Mounting Height	1U	
External Dimensions (WxDxH)	483mm x 457.2mm x 88.0mm	
Net Weight	4900g	5380g
Certifications	CE, RoHS	

Use of Trademarks, Registered Trademarks, and other Protected Names and Symbols

This manual may make reference to trademarks, registered trademarks, and other protected names and/or symbols of third-party companies not related in any way to StarTech.com. Where they occur these references are for illustrative purposes only and do not represent an endorsement of a product or service by StarTech.com, or an endorsement of the product(s) to which this manual applies by the third-party company in question. Regardless of any direct acknowledgement elsewhere in the body of this document, StarTech.com hereby acknowledges that all trademarks, registered trademarks, service marks, and other protected names and/or symbols contained in this manual and related documents are the property of their respective holders.

Technical Support

StarTech.com's lifetime technical support is an integral part of our commitment to provide industry-leading solutions. If you ever need help with your product, visit www.startech.com/support and access our comprehensive selection of online tools, documentation, and downloads.

For the latest drivers/software, please visit www.startech.com/downloads

Warranty Information

This product is backed by a lifetime warranty.

In addition, StarTech.com warrants its products against defects in materials and workmanship for the periods noted, following the initial date of purchase. During this period, the products may be returned for repair, or replacement with equivalent products at our discretion. The warranty covers parts and labor costs only. StarTech.com does not warrant its products from defects or damages arising from misuse, abuse, alteration, or normal wear and tear.

Limitation of Liability

In no event shall the liability of StarTech.com Ltd. and StarTech.com USA LLP (or their officers, directors, employees or agents) for any damages (whether direct or indirect, special, punitive, incidental, consequential, or otherwise), loss of profits, loss of business, or any pecuniary loss, arising out of or related to the use of the product exceed the actual price paid for the product. Some states do not allow the exclusion or limitation of incidental or consequential damages. If such laws apply, the limitations or exclusions contained in this statement may not apply to you.