

2U Heavy Duty Mid-Mount Fixed / Vented Rack Mount Shelf for 2 Post Racks

CABSHF2POST/CABSHF2POSTV

DE: Bedienungsanleitung - de.startech.com

FR: Guide de l'utilisateur - fr.startech.com

ES: Guía del usuario - es.startech.com

IT: Guida per l'uso - it.startech.com

NL: Gebruiksaanwijzing - nl.startech.com

PT: Guia do usuário - pt.startech.com

Packaging Contents

- 1 x Shelf Body
- 4 x Mounting Brackets
- 8 x #10-32 UNF, 3/8" L Screws
- 8 x #10-32 UNF Nuts
- 8 x #10-32 UNF, 5/8" L Panel Screws
- 8 x #10-32 UNF Cage Nuts



*actual product may vary from photos

Installation

1. Locate a suitable location in the rack/cabinet to mount the shelf - the shelf itself requires 2U of space.
2. If the rack uses square mounting holes, install the included #10-32 UNF cage nuts into the square mounting holes on the posts of the rack (front and back).



3. Using the #10-32 UNF, 5/8" L Panel Screws, install the 4 included mounting brackets on either side of your 2 post rack, with the flat portion of the bracket facing inward



4. Place the shelf into the rack and align the mounting holes on the sides of the shelf with the mounting brackets that were installed in the previous step.
5. Use the provided #10-32 UNF, 3/8" L screws and #10-32 UNF nuts to secure the shelf to its brackets on both sides.




6. Make sure the screws are properly tightened and the shelf has no movement before attempting to place anything on the shelf. Be sure to observe the maximum weight capacity of the shelf.

Specifications


	CABSHF2POST	CABSHF2POSTV
Description	2U Heavy Duty Mid-Mount Fixed Rack Mount Shelf for 2 Post Racks	2U Heavy Duty Mid-Mount Vented Rack Mount Shelf for 2 Post Racks
Material	SPCC (1.6mm thick)	
Color	Black	
Max Weight Capacity	150lbs / 67kg	
Mounting Height	2U	
External Dimensions (WxDxH)	484mm x 552mm x 88mm	
Net Weight	4360g	4120g
Certifications	CE, RoHS	

Adjustable Mounting Range

Bottom View:

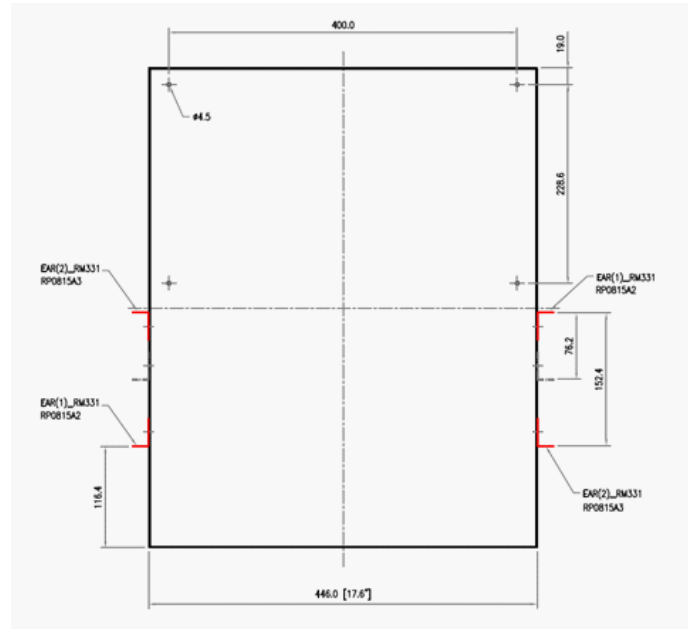

Side View:

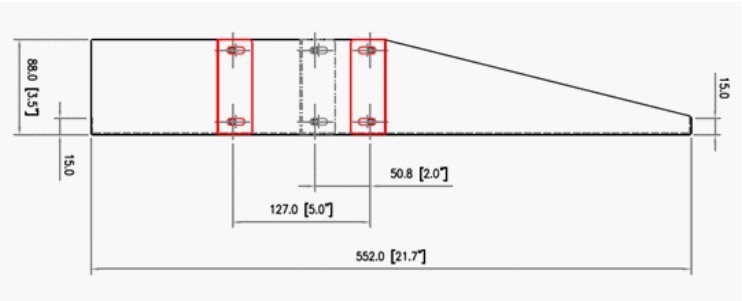

Use of Trademarks, Registered Trademarks, and other Protected Names and Symbols

This manual may make reference to trademarks, registered trademarks, and other protected names and/or symbols of third-party companies not related in any way to StarTech.com. Where they occur these references are for illustrative purposes only and do not represent an endorsement of a product or service by StarTech.com, or an endorsement of the product(s) to which this manual applies by the third-party company in question. Regardless of any direct acknowledgement elsewhere in the body of this document, StarTech.com hereby acknowledges that all trademarks, registered trademarks, service marks, and other protected names and/or symbols contained in this manual and related documents are the property of their respective holders.

Technical Support

StarTech.com's lifetime technical support is an integral part of our commitment to provide industry-leading solutions. If you ever need help with your product, visit www.startech.com/support and access our comprehensive selection of online tools, documentation, and downloads.

For the latest drivers/software, please visit www.startech.com/downloads

Warranty Information

This product is backed by a lifetime warranty.

In addition, StarTech.com warrants its products against defects in materials and workmanship for the periods noted, following the initial date of purchase. During this period, the products may be returned for repair, or replacement with equivalent products at our discretion. The warranty covers parts and labor costs only. StarTech.com does not warrant its products from defects or damages arising from misuse, abuse, alteration, or normal wear and tear.

Limitation of Liability

In no event shall the liability of StarTech.com Ltd. and StarTech.com USA LLP (or their officers, directors, employees or agents) for any damages (whether direct or indirect, special, punitive, incidental, consequential, or otherwise), loss of profits, loss of business, or any pecuniary loss, arising out of or related to the use of the product exceed the actual price paid for the product. Some states do not allow the exclusion or limitation of incidental or consequential damages. If such laws apply, the limitations or exclusions contained in this statement may not apply to you.