

## 1U Low Profile 70mm Socket 775 CPU Cooler

FAN7751U

DE: Bedienungsanleitung - de.startech.com

FR: Guide de l'utilisateur - fr.startech.com

ES: Guía del usuario - es.startech.com

IT: Guida per l'uso - it.startech.com

NL: Gebruiksaanwijzing - nl.startech.com

PT: Guia do usuário - pt.startech.com

### Features

- Thermal transfer compound ensures quick, professional quality installation
- All-copper, skive fin heatsink

### Package Contents

- Fan/heatsink (1)
- Mounting bracket kit (1)
- Screw-top fasteners (4)
- Thermal compound (1)
- Instruction Manual (1)

### Before You Begin

#### System Requirements


- Socket T LGA 775 CPU
- 1 available TX3 power connector
- Phillips screwdriver (optional)

### Installation

Caution! Installing FAN7751U requires that you open your computer case to disconnect and reconnect wires. If you are unfamiliar with this kind of work, consider bringing your computer to your local computer store for help.



\*actual product may vary from photos

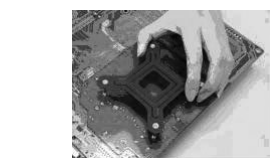

1. Place the base clip backing onto the backside of the mainboard



2. Apply enough thermal paste to the top of the CPU to cover the entire top surface.



3. Remove the protective film from the CPU Cooler



4. Place the CPU Cooler over the CPU, aligning the holes on the CPU Cooler with the base clip posts.



5. Fasten the CPU Cooler to the posts, using the screwtops provided. (Phillips screwdriver is optional)



6. Connect the fan's power cable to the appropriate socket on the mainboard.



7. Installation is complete.

## Specifications

CPU Supported	Socket 775 (Socket T)
Power Adapter	TX3
Cables	220-250mm
DC Fan Size	70x70x10mm
Base Material	All copper (CU-1100)
Bearing Type	Dual Ball Bearing
Speed	4500±10% RPM
Noise Level	<39 dBA
Air Flow (Max.)	30.79 CFM
Rated Voltage	12V

### Use of Trademarks, Registered Trademarks, and other Protected Names & Symbols

This manual may make reference to trademarks, registered trademarks, and other protected names and/or symbols of third-party companies not related in any way to StarTech.com. Where they occur these references are for illustrative purposes only and do not represent an endorsement of a product or service by StarTech.com, or an endorsement of the product(s) to which this manual applies by the third-party company in question. Regardless of any direct acknowledgement elsewhere in the body of this document, StarTech.com hereby acknowledges that all trademarks, registered trademarks, service marks, and other protected names and/or symbols contained in this manual and related documents are the property of their respective holders.

### Technical Support

StarTech.com's lifetime technical support is an integral part of our commitment to provide industry-leading solutions. If you ever need help with your product, visit [www.startech.com/support](http://www.startech.com/support) and access our comprehensive selection of online tools, documentation, and downloads.

### Warranty Information

This product is backed by a two year warranty.

In addition, StarTech.com warrants its products against defects in materials and workmanship for the periods noted, following the initial date of purchase. During this period, the products may be returned for repair, or replacement with equivalent products at our discretion. The warranty covers parts and labor costs only. StarTech.com does not warrant its products from defects or damages arising from misuse, abuse, alteration, or normal wear and tear.

### Limitation of Liability

In no event shall the liability of StarTech.com Ltd. and StarTech.com USA LLP (or their officers, directors, employees or agents) for any damages (whether direct or indirect, special, punitive, incidental, consequential, or otherwise), loss of profits, loss of business, or any pecuniary loss, arising out of or related to the use of the product exceed the actual price paid for the product. Some states do not allow the exclusion or limitation of incidental or consequential damages. If such laws apply, the limitations or exclusions contained in this statement may not apply to you.