



MPO/MTP to LC Breakout Cable - Plenum-Rated - OM3, 40Gb - Push/Pull-Tab - XX m

MPO8LCPLXXM

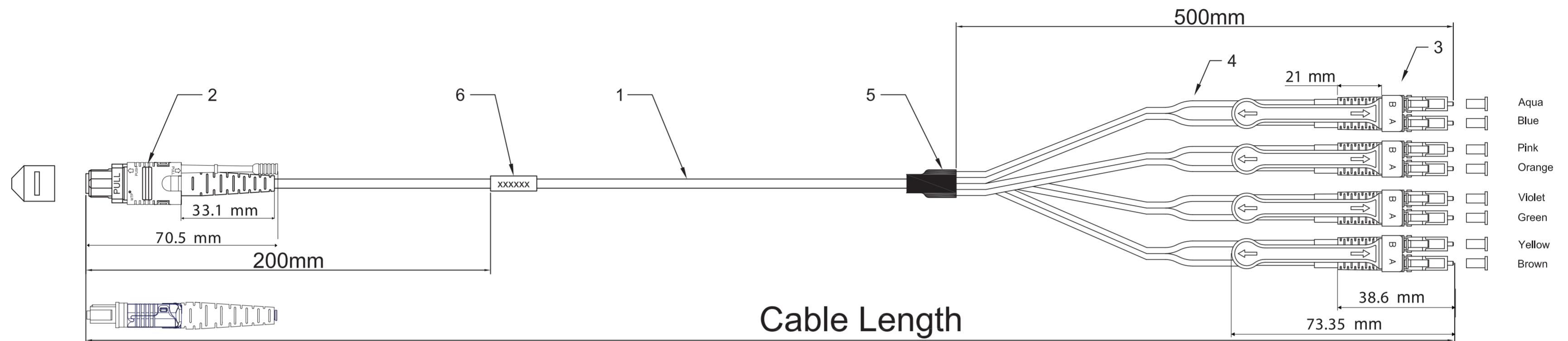

Cable Length

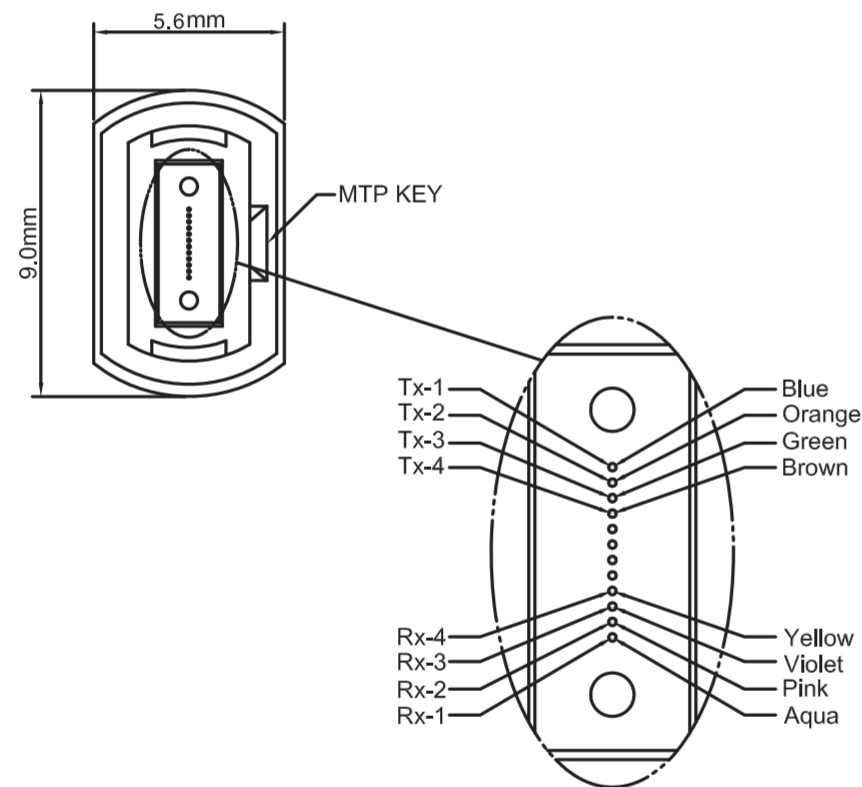

Insertion loss $\leq 0.5\text{dB(MTP)}$ $\leq 0.2\text{ dB(LC)}$
 Return loss $\geq 20\text{dB(MTP)}$ $\geq 35\text{dB(LC)}$

SKU Name (SKU)	Length	Cable Length	Tolerance
MPO8LCPL1M	1M	Length $\leq 1\text{M}$	+5cm
MPO8LCPL2M	2M	1M < Length < 10M	+10cm
MPO8LCPL3M	3M		
MPO8LCPL5M	5M		
MPO8LCPL10M	10M	Length $\geq 10\text{M}$	$\pm 1\%$
MPO8LCPLXM	XM		

6	1	Cable label
5	1	Fanout Kit
4	A/R	OD: 2.0mm Duplex Aqua
3	4	LC/PC MM Duplex Connector (Beige Housing White Boot) Pull Tab
2	1	MTP(Female)/PC MM 12Fibers Connector (Aqua Housing Black Boot) Pull Tab
1	A/R	OD: 3.0mm, Multimode 50/125 OM3, 12Fibers Single Jacket Micro Cable, OFNP, Color: Aqua