


PART NUMBER	LENGTH	TOLERANCE
N6PATC50CMyy	500mm	+20/-0mm
N6PATC1Myy	1000mm	+20/-0mm
N6PATC150CMyy	1500mm	+25/-0mm
N6PATC2Myy	2000mm	+30/-0mm
N6PATC3Myy	3000mm	+30/-0mm
N6PATC5Myy	5000mm	+40/-0mm
N6PATC7Myy	7000mm	+40/-0mm
N6PATC750CMyy	7500mm	+80/-0mm
N6PATC10Myy	10000mm	+80/-0mm
N6PATC15Myy	15000mm	+80/-0mm

COLOR	CODE (yy)
GRAY	GR
BLUE	BL
BLACK	BK
GREEN	GN
ORANGE	OR
PURPLE	PL
WHITE	WH
RED	RD
YELLOW	YL

PINOUT:

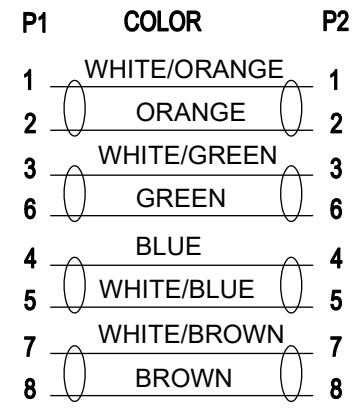

SPEC:

- CABLE CM TYPE 24AWG 4PR 75°C TIA/EIA-568B 2-1 CAT 6 UTP 650MHZ
JACKET PVC COLOR: yy OD:6.1mm (PRINTING " StarTech.com ")
- CONNECTOR CAT6 RJ45 8P8C LONG TELEPHONE PLUG GOLD PLATED CONTACTS
- MOLDING PVC COLOR: yy
- MOLDING PVC COLOR: YELLOW(PANTONE 123C)

NOTE: Complies with IEEE 802.3bt Type4 standard

THIRD ANGLE PROJECTION 		StarTech.com	
GENERAL NOTES DIMENSIONS ARE IN MM - DO NOT SCALE		PRODUCT ID	N6PATCxxMyy
THIS DOCUMENT CONTAINS CONFIDENTIAL, PROPRIETARY INFORMATION THAT IS PROPERTY OF STARTECH.COM		DESCRIPTION	CAT6 Snagless Gigabit Ethernet Cable - 650MHz 100W PoE RJ45 UTP
		DO NOT SCALE	SHEET: 1 OF: 1
		UPLOAD DATE: 3/20/2023	