

## 8U/ 10U/ 12U 19in Wide Wall Mount Side Mount Deep Open Frame Rack Cabinet

RK819SIDEM / RK1019SIDEM / RK1219SIDEM

DE: Bedienungsanleitung - de.startech.com

FR: Guide de l'utilisateur - fr.startech.com

ES: Guía del usuario - es.startech.com

IT: Guida per l'uso - it.startech.com

NL: Gebruiksaanwijzing - nl.startech.com

PT: Guia do usuário - pt.startech.com

**WARNING!** To prevent bodily injury, please ensure that the rack is installed in a structurally sound environment with a level floor and that all hardware has been assembled securely, and checked for stability before loading equipment. When installing equipment into the rack, start from the bottom of the rack first and move upwards, keeping the heaviest equipment at the bottom to avoid a situation where the rack becomes top-heavy.

### Packaging Contents

- 1 x Wall Mount Cabinet
- 1 x Bag of M5 Cabinet Screw
- 1 x Bag of M5 Cage Nut

### System Requirements

- If mounting to a wall or other surface: Appropriate mounting hardware for surface type


### Installation

To mount the cabinet to a wall, there are 4 anchor points on the side panel of the cabinet. Please use the appropriate screws or bolts for mounting heavy equipment to the specific type of wall (i.e. concrete, drywall, etc.).

**NOTE:** Mounting points are 16" from center to center for mounting to standard wooden studs.

Ensure the wall and mounting hardware will be able to support the weight of the cabinet and any equipment that will be mounted into it. Please be sure to observe proper safety procedures and use the appropriate tools.

To install rack mountable equipment into the cabinet, use the provided square cage nuts on the rack posts (install from rear of posts), then use the provided cabinet screws to secure the equipment to the cage nuts (from front of posts).

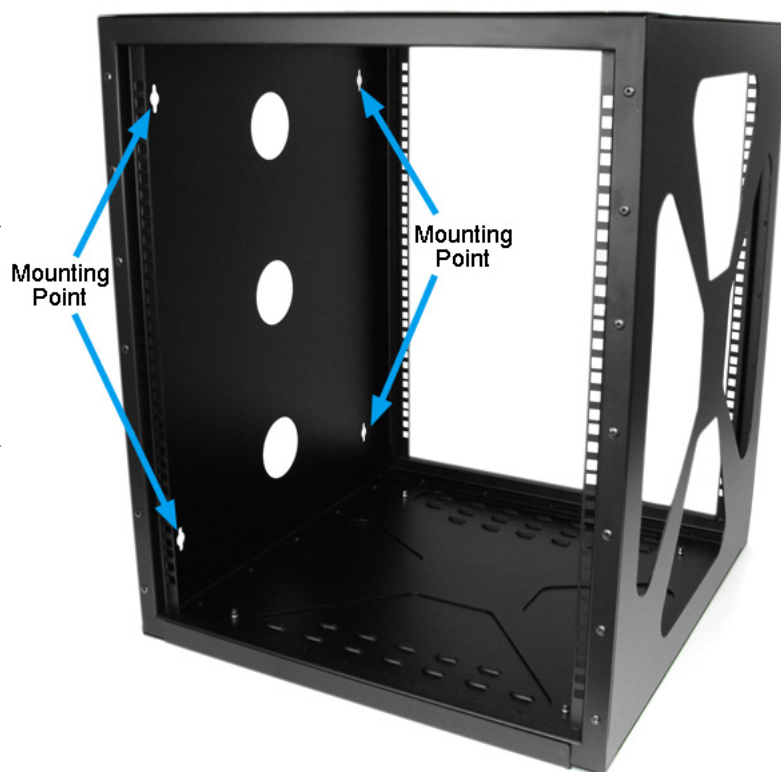

\*RK1219SIDEM shown

\*actual product may vary from photos

## Specifications

	RK819SIDEM	RK1019SIDEM	RK1219SIDEM
<b>Description</b>	8U 19in Wide Wallmount/ Sidemount Open Frame Rack	10U 19in Wide Wallmount/ Sidemount Open Frame Rack	12U 19in Wide Wallmount/ Sidemount Open Frame Rack
<b>Internal Height</b>	8U	10U	12U
<b>Mounting Depth</b>	559.0mm (22")		
<b>Maximum Weight Capacity</b>	159 kg (350 lbs)		
<b>Material</b>	SPCC		
<b>Color</b>	Black		
<b>Equipment Mounting Hole Type</b>	Square		
<b>External Dimensions (WxHxD)</b>	537.0mm x 480.0mm x 565.0mm	537.0mm x 570.0mm x 565.0mm	537.0mm x 655.0mm x 558.0mm
<b>Net Weight</b>	17.72 kg	19.36 kg	21.82kg
<b>Standards</b>	EIA RS310-D		
<b>Certifications</b>	CE, RoHS		

## Use of Trademarks, Registered Trademarks, and other Protected Names and Symbols

This manual may make reference to trademarks, registered trademarks, and other protected names and/or symbols of third-party companies not related in any way to StarTech.com. Where they occur these references are for illustrative purposes only and do not represent an endorsement of a product or service by StarTech.com, or an endorsement of the product(s) to which this manual applies by the third-party company in question. Regardless of any direct acknowledgement elsewhere in the body of this document, StarTech.com hereby acknowledges that all trademarks, registered trademarks, service marks, and other protected names and/or symbols contained in this manual and related documents are the property of their respective holders.

## Technical Support

StarTech.com's lifetime technical support is an integral part of our commitment to provide industry-leading solutions. If you ever need help with your product, visit [www.startech.com/support](http://www.startech.com/support) and access our comprehensive selection of online tools, documentation, and downloads.

For the latest drivers/software, please visit [www.startech.com/downloads](http://www.startech.com/downloads)

## Warranty Information

This product is backed by a lifetime warranty.

In addition, StarTech.com warrants its products against defects in materials and workmanship for the periods noted, following the initial date of purchase. During this period, the products may be returned for repair, or replacement with equivalent products at our discretion. The warranty covers parts and labor costs only. StarTech.com does not warrant its products from defects or damages arising from misuse, abuse, alteration, or normal wear and tear.

## Limitation of Liability

In no event shall the liability of StarTech.com Ltd. and StarTech.com USA LLP (or their officers, directors, employees or agents) for any damages (whether direct or indirect, special, punitive, incidental, consequential, or otherwise), loss of profits, loss of business, or any pecuniary loss, arising out of or related to the use of the product exceed the actual price paid for the product. Some states do not allow the exclusion or limitation of incidental or consequential damages. If such laws apply, the limitations or exclusions contained in this statement may not apply to you.