


## Anti-Fatigue Standing Desk Mat - Contoured

### Product Diagram (STSMATC)

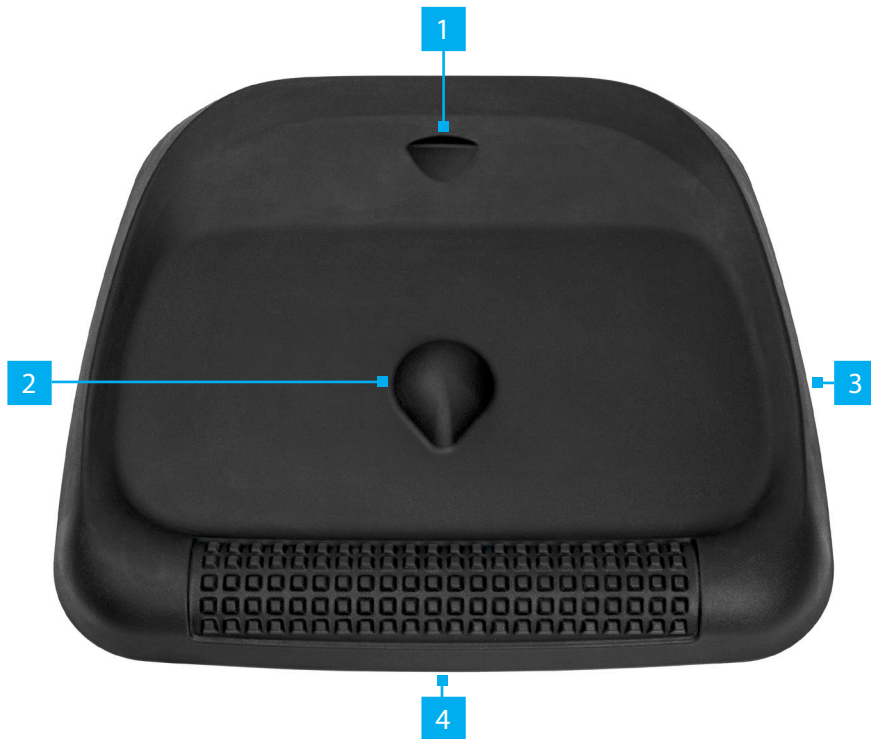

Part	Function
1 Heel Grip	• For re-positioning the Anti-Fatigue Standing Desk Mat
2 Teardrop Flex Center	• For massaging the arches of your foot
3 Raised Side Panels	• For varying your stance
4 Textured Massage Bar	• For calf stretches, core balancing, or foot massages

### Warning Statements

**Read all warning statements before using the Anti-Fatigue Standing Desk Mat.**

- The Anti-Fatigue Standing Desk Mat, by design, has an uneven standing surface which can pose a risk to users who become unbalanced when shifting their weight around; as a result, caution should be exercised when mounting, dismounting and/or using the Anti-Fatigue Standing Desk Mat, as personal injury and/or equipment damage can result from a fall.
- While using the Anti-Fatigue Standing Desk Mat, always wear appropriate footwear.
  - Note:** Running shoes and other flat-soled shoes are recommended.
- Consult a physician before using the Anti-Fatigue Standing Desk Mat.
- Use the Anti-Fatigue Standing Desk Mat on a firm, flat, dry, and level surface.
- The Anti-Fatigue Standing Desk Mat can present a tripping hazard. Always store the Anti-Fatigue Standing Desk Mat in a location with no foot traffic.
- Use water and vinegar to clean the Anti-Fatigue Standing Desk Mat. Soaps may leave behind residue that can create a slippery surface. Always ensure the Anti-Fatigue Standing Desk Mat is completely dry before resuming use.
- Keep the Anti-Fatigue Standing Desk Mat away from heat sources. Excessive heat can damage the Anti-Fatigue Standing Desk Mat, creating a hazardous surface to stand on.
- Individuals under the age of 18 should be supervised by an adult when using the Anti-Fatigue Standing Desk Mat.

### Requirements

- A flat, level surface for use
- (For cleaning) water and vinegar

For additional details, please visit [www.startech.com/STSMATC](http://www.startech.com/STSMATC).

#### **For the State of California**

⚠ **WARNING:** Cancer and Reproductive Harm - [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)

#### **Use of Trademarks, Registered Trademarks, and other Protected Names and Symbols**

This manual may make reference to trademarks, registered trademarks, and other protected names and/or symbols of third-party companies not related in any way to StarTech.com. Where they occur these references are for illustrative purposes only and do not represent an endorsement of a product or service by StarTech.com, or an endorsement of the product(s) to which this manual applies by the third-party company in question. StarTech.com hereby acknowledges that all trademarks, registered trademarks, service marks, and other protected names and/or symbols contained in this manual and related documents are the property of their respective holders.

#### **Warranty Information**

This product is backed by a two-year warranty.

For further information on product warranty terms and conditions, please refer to [www.startech.com/warranty](http://www.startech.com/warranty).

#### **Limitation of Liability**

In no event shall the liability of StarTech.com Ltd. and StarTech.com USA LLP (or their officers, directors, employees or agents) for any damages (whether direct or indirect, special, punitive, incidental, consequential, or otherwise), loss of profits, loss of business, or any pecuniary loss, arising out of or related to the use of the product exceed the actual price paid for the product. Some states do not allow the exclusion or limitation of incidental or consequential damages. If such laws apply, the limitations or exclusions contained in this statement may not apply to you.

<b>StarTech.com Ltd.</b>	<b>StarTech.com LLP</b>	<b>StarTech.com Ltd.</b>	FR: fr.startech.com
45 Artisans Cres	2500 Creekside	Unit B, Pinnacle 15	DE: de.startech.com
London, Ontario	Parkwy	Gowerton Rd,	ES: es.startech.com
N5V 5E9	Lockbourne, Ohio	Brackmills	NL: nl.startech.com
Canada	43137	Northampton	IT: it.startech.com
	U.S.A.	NN4 7BW	JP: jp.startech.com
		United Kingdom	