

USB 2.0 to 10/100Mbps Fast Ethernet Network Adapter Dongle

USB2100



*actual product may vary from photos

DE: Bedienungsanleitung - de.startech.com

FR: Guide de l'utilisateur - fr.startech.com

ES: Guía del usuario - es.startech.com

IT: Guida per l'uso - it.startech.com

NL: Gebruiksaanwijzing - nl.startech.com

PT: Guia do usuário - pt.startech.com

For the most up-to-date information, please visit: www.startech.com



FCC Compliance Statement

This equipment has been tested and found to comply with the limits for a Class B digital device, pursuant to Part 15 of the FCC Rules. These limits are designed to provide reasonable protection against harmful interference in a residential installation. This equipment generates, uses, and can radiate radio frequency energy and, if not installed and used in accordance with the instructions, may cause harmful interference to radio communications. However, there is no guarantee that interference will not occur in a particular installation. If this equipment does cause harmful interference to radio or television reception, which can be determined by turning the equipment off and on, the user is encouraged to try to correct the interference by one or more of the following measures:

- Reorient or relocate the receiving antenna.
- Increase the separation between the equipment and receiver.
- Connect the equipment to an outlet on a different circuit than the receiver.
- Consult the dealer or an experienced radio/TV technician for help.

Any changes or modifications not expressly approved by the party responsible for compliance could void the user's authority to operate the device. If shielded interface cables are included with the product, or if additional components or accessories are designated for use with the installation, they must be used to ensure compliance with FCC regulations.

ISED Statement / Déclaration d'ISDE

CAN ICES-003(B) / NMB-003(B)

This Class B digital apparatus complies with Canadian ICES-003.

Cet appareil numérique de la classe B est conforme à la norme NMB-003 du Canada.

This device complies with ISED Canada licence-exempt RSS standard(s). Operation is subject to the following two conditions: (1) this device may not cause interference, and (2) this device must accept any interference, including interference that may cause undesired operation of the device.

Le présent appareil est conforme aux CNR d'ISDE Canada applicables aux appareils radio exempts de licence. L'exploitation est autorisée aux deux conditions suivantes : (1) l'appareil ne doit pas produire de brouillage, et (2) l'appareil doit accepter tout brouillage radioélectrique subi, même si le brouillage est susceptible d'en compromettre le fonctionnement.

Use of Trademarks, Registered Trademarks, and other Protected Names and Symbols

This manual may make reference to trademarks, registered trademarks, and other protected names and/or symbols of third-party companies not related in any way to StarTech.com. Where they occur these references are for illustrative purposes only and do not represent an endorsement of a product or service by StarTech.com, or an endorsement of the product(s) to which this manual applies by the third-party company in question. Regardless of any direct acknowledgement elsewhere in the body of this document, StarTech.com hereby acknowledges that all trademarks, registered trademarks, service marks, and other protected names and/or symbols contained in this manual and related documents are the property of their respective holders.

Table of Contents

Introduction	2
Packaging Contents	2
System Requirements.....	2
LED Indicators	2
Installation	2
Windows.....	2
Mac OS	3
Verifying Installation	3
Windows.....	3
Mac OS	4
Specifications.....	5
Technical Support	6
Warranty Information.....	6

Introduction

Packaging Contents

- 1 x USB 2.0 Fast Ethernet Adapter
- 1 x Instruction Manual

System Requirements

- Available USB port
- Windows® 11 / 10 / 8 / 8.1 (32/64bit), 7 (32/64), Vista(32/64), XP(32/64), Windows Server® 2022, 2019, 2016, 2012, 2008 R2, 2003(32/64), Mac OS® 10.6 to 10.15, 11.3 to 14.0, Google Chrome OS™, Linux 2.6.x and up - LTS Versions only

LED Indicators

Power (Green)	Solid: Connection to a 100Mbps network detected Off: Connection to a 10Mbps network, or not connected
Link (Yellow)	Flashing: LAN activity

Installation

Windows

1. Navigate to www.StarTech.com/USB2100, and click the Support tab.
2. Click the “[asix ax88772c] windows usb ethernet adapter.zip” file and download the drivers.
3. Right-click the zip folder that you downloaded, select Extract All, and follow the onscreen instructions.
4. Right-click Setup.exe
5. Click Run as Administrator.

Note: If the Run as Administrator option is not available, you might be attempting to run the installer from within the zipped file. Extract the files using the instructions in Step 3

6. Follow the on-screen prompts to install the device drivers and restart the computer when prompted
7. Your computer will automatically complete the driver installation and your device should be ready to use.


Mac OS

1. Navigate to www.StarTech.com/USB2100, and click the Support tab.
2. Click the “[asix ax88772c] mac usb ethernet adapter.zip” file and download the drivers.
3. Double-click the [ASIX AX88772C] USB Ethernet Adapter.zip file.
4. Double-click the Mac folder.
5. Press and hold the Control key and click the dmg file.
6. To mount a drive on the desktop, click Open.
7. Double-click the drive that you just mounted on the desktop.
8. Press and hold the Control key and click the setup file.
9. Click Open.
10. Complete the instructions to install the device drivers, and restart your computer when prompted to.
11. After your computer restarts, connect the device to your computer.

Verifying Installation


Windows

1. Open the Windows Device Manager.
2. Expand the “Network adapters” section. On a successful install, you should see the following device installed with no exclamation points or question marks.

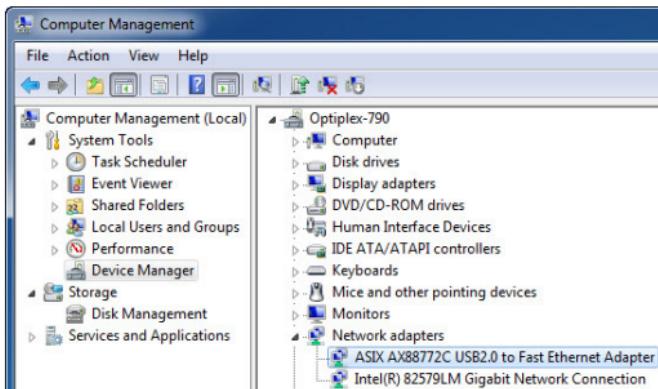

Mac OS

1. Open the System Profiler by clicking the Apple symbol in the top left corner, selecting **About this Mac**, then select **System Report**.
2. Expand the "USB" section. With the adapter connected, you should see the following device in the list.

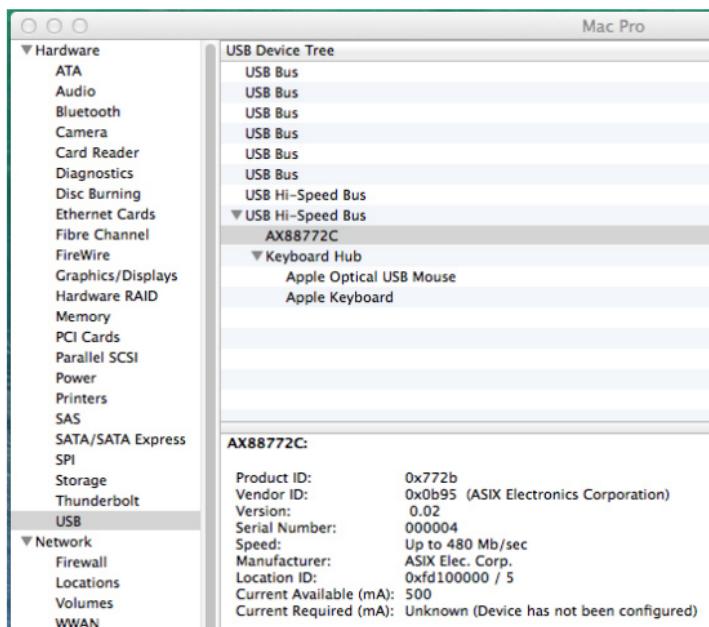

Specifications

Host Interface	USB 2.0
Chipset	ASIX - AX88772C
Connectors	1 x RJ-45 Female 1 x USB 2.0 type A Male
Maximum Data Transfer Rate	USB 2.0: 480 Mbps LAN: 200 Mbps (Full-Duplex)
Supported Standards	IEEE802.3i, IEEE 802.3u
Supported Network Link Speeds	10/ 100 Mbps
Ethernet Full Duplex Support	Yes
Auto MDIX	Yes
Power	USB-Powered
Enclosure Material	Plastic
Operating Temperature	10°C to 40°C (50°F to 114°F)
Storage Temperature	-20°C to 70°C (-4°F to 158°F)
Humidity	10~90% RH
Cable Length	150 mm
Dimensions	66 x 22 x 17 mm
Weight	49 g
Compatible Operating Systems	Windows® 11 / 10 / 8 / 8.1 (32/64bit), 7 (32/64), Vista(32/64), XP(32/64), Windows Server® 2022, 2019, 2016, 2012, 2008 R2, 2003(32/64), Mac OS® 10.6 to 10.15, 11.3 to 14.0, Google Chrome OS™, Linux 2.6.x and up - LTS Versions only

Technical Support

StarTech.com's lifetime technical support is an integral part of our commitment to provide industry-leading solutions. If you ever need help with your product, visit **www.startech.com/support** and access our comprehensive selection of online tools, documentation, and downloads.

For the latest drivers/software, please visit **www.startech.com/downloads**

Warranty Information

This product is backed by a two year warranty.

In addition, StarTech.com warrants its products against defects in materials and workmanship for the periods noted, following the initial date of purchase. During this period, the products may be returned for repair, or replacement with equivalent products at our discretion. The warranty covers parts and labor costs only. StarTech.com does not warrant its products from defects or damages arising from misuse, abuse, alteration, or normal wear and tear.

Limitation of Liability

In no event shall the liability of StarTech.com Ltd. and StarTech.com USA LLP (or their officers, directors, employees or agents) for any damages (whether direct or indirect, special, punitive, incidental, consequential, or otherwise), loss of profits, loss of business, or any pecuniary loss, arising out of or related to the use of the product exceed the actual price paid for the product. Some states do not allow the exclusion or limitation of incidental or consequential damages. If such laws apply, the limitations or exclusions contained in this statement may not apply to you.





Hard-to-find made easy®

Hard-to-find made easy. At StarTech.com, that isn't a slogan. It's a promise.

StarTech.com is your one-stop source for every connectivity part you need. From the latest technology to legacy products — and all the parts that bridge the old and new — we can help you find the parts that connect your solutions.

We make it easy to locate the parts, and we quickly deliver them wherever they need to go. Just talk to one of our tech advisors or visit our website. You'll be connected to the products you need in no time.

Visit www.startech.com for complete information on all StarTech.com products and to access exclusive resources and time-saving tools.

StarTech.com is an ISO 9001 Registered manufacturer of connectivity and technology parts. StarTech.com was founded in 1985 and services a worldwide market.