
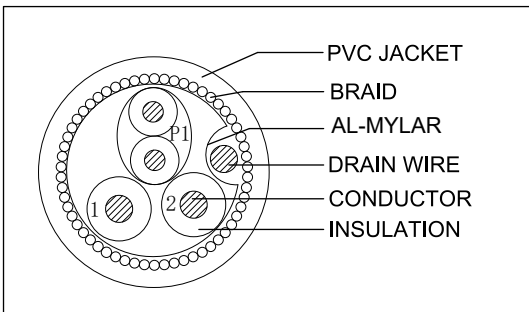
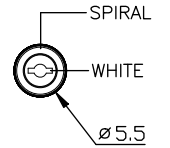


▼Length

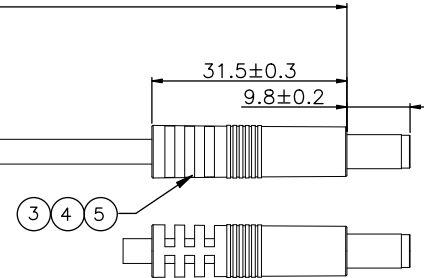

PIN ASSIGNMENT

P1	P2
1	RED 1
4	BLACK 2

- NOTE:
1. OPEN/SHORT/INTERMITTENCE 100% TEST.
 2. DIELECTRIC STRENGTH:200 VOLTS AC 2mA MAX/0.02S.
 3. INSULATION RESISTANCE:300V DC/0.02SEC, 10MΩ MIN.
 4. CONDUCTIVE RESISTANCE:2Ω MAX.
 5. RoHS COMPLIANT.

SKU	LENGTH
USB2TYPEM	915MM+30/-0MM
USB2TYPEM2M	2000MM+40/-0MM

NO.	NAME	MATERIAL DESCRIPTION
5	INNER MOLD	LD-PE
4	OVER MOLD	PVC , COLOR:BLACK
3	CONNECTOR	Ø5.5*Ø2.1*22.5 DC PLUG,NICKEL PLATED FOR SHELL AND PIN BLACK INSULATION.
2	CONNECTOR	USB A/M (SOLDER TYPE) PIN: G/F, NICKEL PLATED FOR SHELL,WHITE INSULATION.
1	CABLE	USB 2.0 UL2725 28#*1P+28#*2C+AL+D(7/0.12TC)+B(16*3/0.12AL-M) OD:3.8mm BLACK PVC JACKET

THIRD ANGLE PROJECTION

GENERAL NOTES
 DIMENSIONS ARE IN MM - DO NOT SCALE
 THIS DOCUMENT CONTAINS CONFIDENTIAL, PROPRIETARY INFORMATION THAT IS PROPERTY OF STARTECH.COM

StarTech.com

PRODUCT ID	USB2TYPEMx
DESCRIPTION	USB to 5.5mm Power Cable - Type M Barrel
DO NOT SCALE	SHEET: 1 OF: 1
UPLOAD DATE: 3/09/2026	