

DVI2MDPA

DVI to Mini DisplayPort Converter with 2 Channel Audio

StarTech.com

Hard-to-find made easy


Installation Guide

Packaging Contents

- 1 x DVI to Mini DisplayPort with audio converter
- 1 x 3.5mm mini-jack cable
- 1 x USB mini-B cable
- 1 x installation Guide

System Requirements

- Mini DisplayPort enabled display device (i.e. monitor, projector, HDTV, etc)
- DVI-D enabled video source (i.e. computer, laptop, etc)
- Available USB port on video source device
- OPTIONAL: 3.5mm stereo mini-jack audio output on video source device

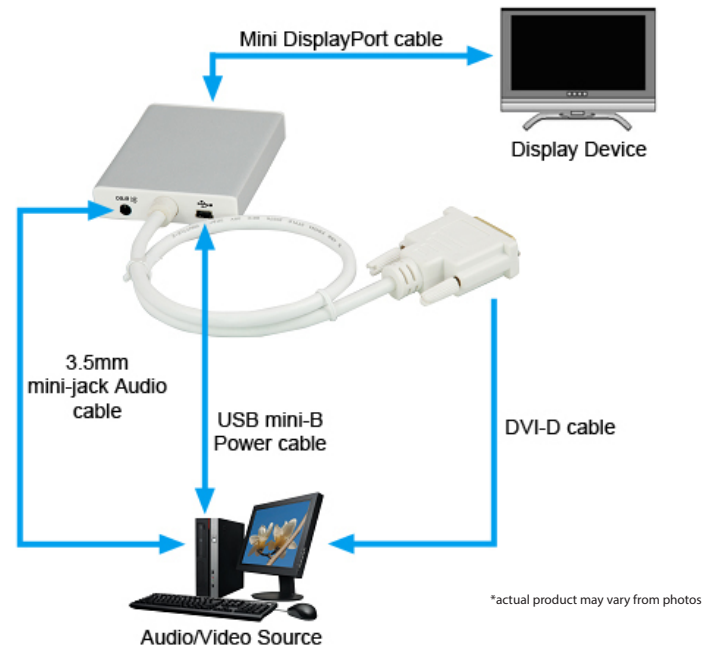

Installation

1. Make sure the video display device (i.e. monitor, projector, HDTV, etc) and video source (i.e. computer, laptop, etc) are turned off, before connecting the converter.
2. Connect the built-in male DVI-D cable and USB mini-B cable from the converter to the video source.
3. Connect a Mini DisplayPort cable (not included) from the converter to the display device.
4. If using audio, connect the 3.5mm mini-jack cable from the converter to the speaker/headphone output on the video source device.
5. Turn on the video display followed by the video source.
6. Once the external display is detected and configured, the video output should be visible on the display device. Some adjustments may be necessary from the video source device's output settings for optimal viewing.

NOTE: If connecting to a 27" or 24" Apple display, it may be necessary to have the video source device set to a screen resolution of 1280x720 or 1920x1200 respectively, BEFORE connecting the converter.

Specifications

Video Signal	Input: DVI (digital) 1.0 Output: DisplayPort 1.1a
Connectors	1 x Mini DisplayPort female 1 x 25-pin DVI-D male 1 x 3.5mm mini-jack female 1 x USB mini-B female
LEDs	1 x Power
Maximum Video Resolution	1920 x 1200 (Single-Link)
HDCP Support	Yes
EDID Support	Yes
Audio Support	Yes (2-channel stereo)
Integrated Cable Length	2 ft
Operating Temperature	0°C ~ 70°C (32°F ~ 158°F)
Storage Temperature	-10°C ~ 80°C (14°F ~ 176°F)
Humidity	10% ~ 85 % RH
Dimensions (LxWxH)	76.2mm x 63.5mm x 6.6mm
Weight	200 g

Warranty Information

This product is backed by a two year warranty.

In addition, StarTech.com warrants its products against defects in materials and workmanship for the periods noted, following the initial date of purchase. During this period, the products may be returned for repair, or replacement with equivalent products at our discretion. The warranty covers parts and labor costs only. StarTech.com does not warrant its products from defects or damages arising from misuse, abuse, alteration, or normal wear and tear.

Limitation of Liability

In no event shall the liability of StarTech.com Ltd. and StarTech.com USA LLP (or their officers, directors, employees or agents) for any damages (whether direct or indirect, special, punitive, incidental, consequential, or otherwise), loss of profits, loss of business, or any pecuniary loss, arising out of or related to the use of the product exceed the actual price paid for the product. Some states do not allow the exclusion or limitation of incidental or consequential damages. If such laws apply, the limitations or exclusions contained in this statement may not apply to you.

Manual Revision:10/17/2016

For the most up-to-date information, please visit www.startech.com