


40/44 Pin IDE to Compact Flash SSD Adapter

IDE2CF

- DE: Bedienungsanleitung - de.startech.com
- FR: Guide de l'utilisateur - fr.startech.com
- ES: Guía del usuario - es.startech.com
- IT: Guida per l'uso - it.startech.com
- NL: Gebruiksaanwijzing - nl.startech.com
- PT: Guia do usuário - pt.startech.com

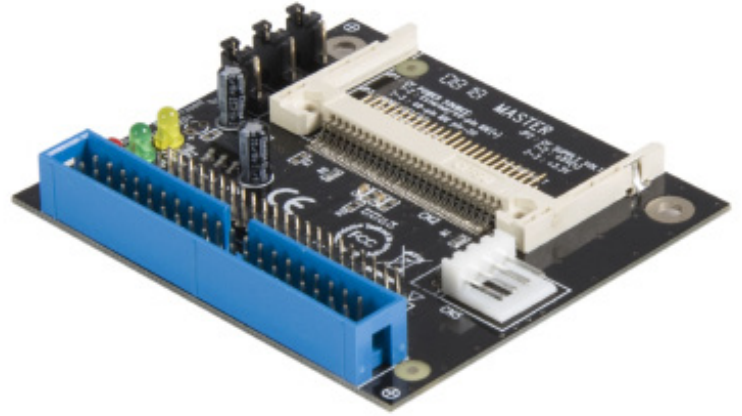

*actual product may vary from photos

Packaging Contents

- IDE2CF adapter
- Installation Guide

System Requirements

- Computer system with available 40 or 44-pin IDE channel

Installation

1. Insert the CompactFlash card into the CN2 slot on the adapter.
2. Change the jumper settings to match your configuration.
3. Mount the adapter inside your computer case.
4. Connect either the 40 or 44-pin IDE ribbon cable from your IDE controller to the appropriate connector on the adapter.
5. Connect the floppy power connector (SP4) from your power supply to the CN5 connector on the adapter.

- **CN2** – CompactFlash socket (Master/Single mode)
- **CN3** – 40-pin (2.54 mm pitch) IDE connector
- **CN4** – 44-pin (2.0 mm pitch) SFF IDE connector
- **CN5** – Floppy disk drive power connector
- **LED1** – CompactFlash card-detect indicator
- **LED2** – Read/Write activity indicator
- **LED3** – Power-on indicator

Jumper Settings

JP1 – CompactFlash power source selection:


1-2 *	External power (CN5) or 44-pin SFF IDE connector (CN4)
2-3	Pin 20 of 40-pin standard IDE connector (CN3), for VIA EPIA series motherboards

JP2 – CompactFlash voltage selection:

1-2 *	+5.0V
2-3	+3.3V

JP3 – CompactFlash mode selection:

1-2 *	Master/Single
2-3	Slave

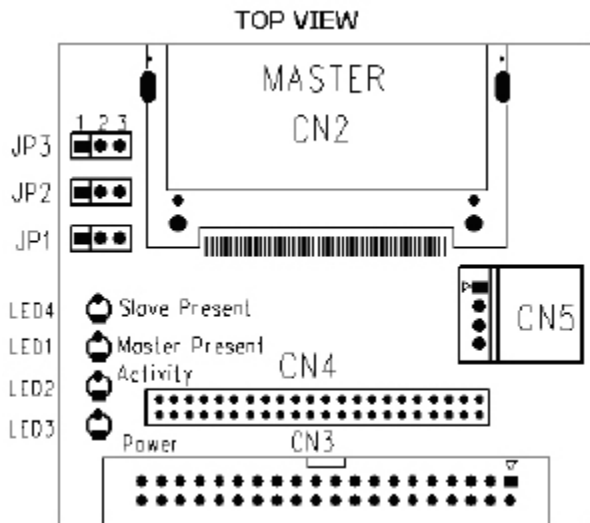

Specifications

Bus Interface	ATA
Connectors	40-pin IDE, 44-pin IDE, SP4 floppy power, CF card slot
LED Indicators	Power, Card Detect, Activity
CompactFlash Compatibility	CF Type I and II, Micro-Drive

Use of Trademarks, Registered Trademarks, and other Protected Names and Symbols

This manual may make reference to trademarks, registered trademarks, and other protected names and/or symbols of third-party companies not related in any way to StarTech.com. Where they occur these references are for illustrative purposes only and do not represent an endorsement of a product or service by StarTech.com, or an endorsement of the product(s) to which this manual applies by the third-party company in question. Regardless of any direct acknowledgement elsewhere in the body of this document, StarTech.com hereby acknowledges that all trademarks, registered trademarks, service marks, and other protected names and/or symbols contained in this manual and related documents are the property of their respective holders.

Technical Support

StarTech.com's lifetime technical support is an integral part of our commitment to provide industry-leading solutions. If you ever need help with your product, visit www.startech.com/support and access our comprehensive selection of online tools, documentation, and downloads.

For the latest drivers/software, please visit www.startech.com/downloads

Warranty Information

This product is backed by a two year warranty.

In addition, StarTech.com warrants its products against defects in materials and workmanship for the periods noted, following the initial date of purchase. During this period, the products may be returned for repair, or replacement with equivalent products at our discretion. The warranty covers parts and labor costs only. StarTech.com does not warrant its products from defects or damages arising from misuse, abuse, alteration, or normal wear and tear.

Limitation of Liability

In no event shall the liability of StarTech.com Ltd. and StarTech.com USA LLP (or their officers, directors, employees or agents) for any damages (whether direct or indirect, special, punitive, incidental, consequential, or otherwise), loss of profits, loss of business, or any pecuniary loss, arising out of or related to the use of the product exceed the actual price paid for the product. Some states do not allow the exclusion or limitation of incidental or consequential damages. If such laws apply, the limitations or exclusions contained in this statement may not apply to you.