
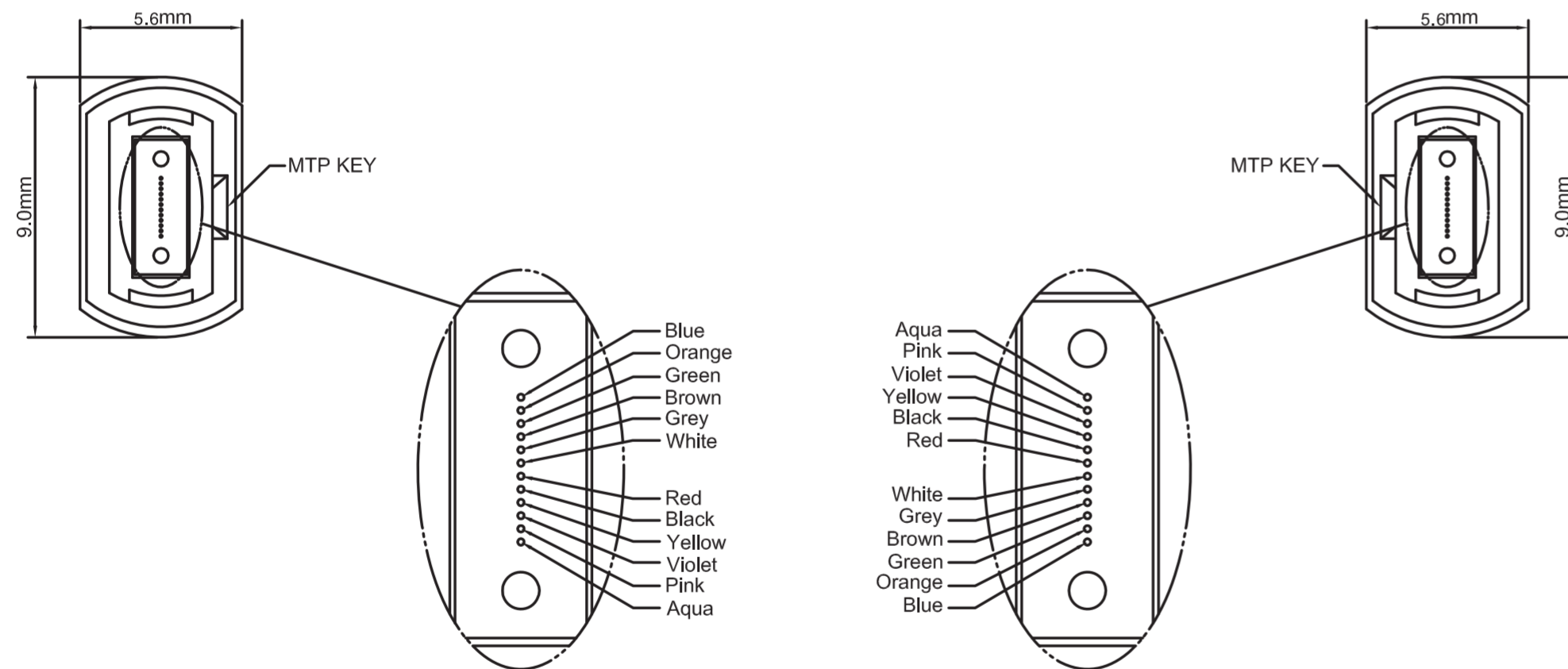


# MPO/MTP Fiber Optic Cable - Plenum-Rated - OM3, 40Gb - Push/Pull-Tab - XX m

MPO12PLXXM

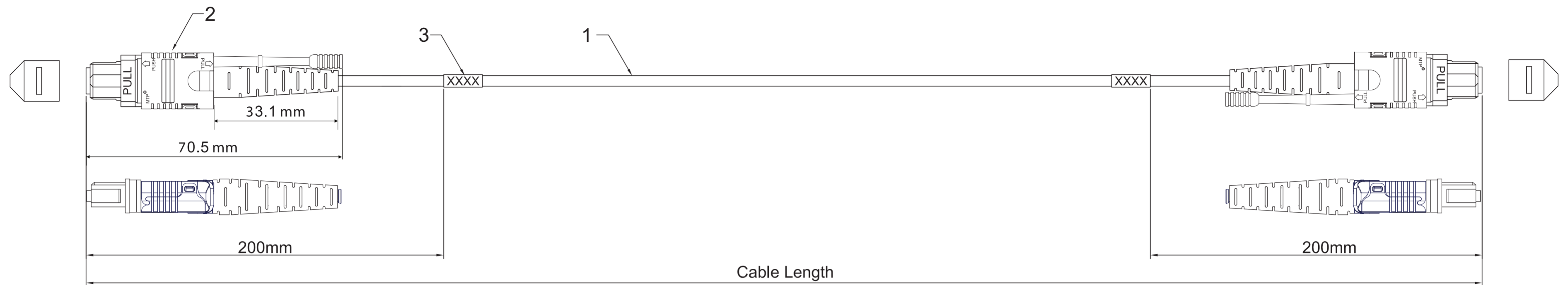

Insertion loss  $\leq 0.5\text{dB}$   
Return loss  $\geq 20\text{dB}$

SKU Name (SKU)	Length	Cable Length	Tolerance
MPO 12PL1M	1M	Length $\leq 1\text{M}$	+5cm
MPO 12PL2M	2M	1M < Length < 10M	+10cm
MPO 12PL3M	3M		
MPO 12PL5M	5M		
MPO 12PL10M	10M	Length $\geq 10\text{M}$	$\pm 1\%$
MPO 12PLXM	XM		

3	2	Serial Number Label
2	2	MTP/PC Female MM 12F Connector (Aqua Housing)
1	A/R	$\varnothing 3.0\text{mm}$ , Multimode OM3 50/125, 12 fibers Single Jacket Micro Cable, OFNP, Color: Aqua