


5-15R to 5-15P XXft Right angled Power Cord Extension

PAC101RXX

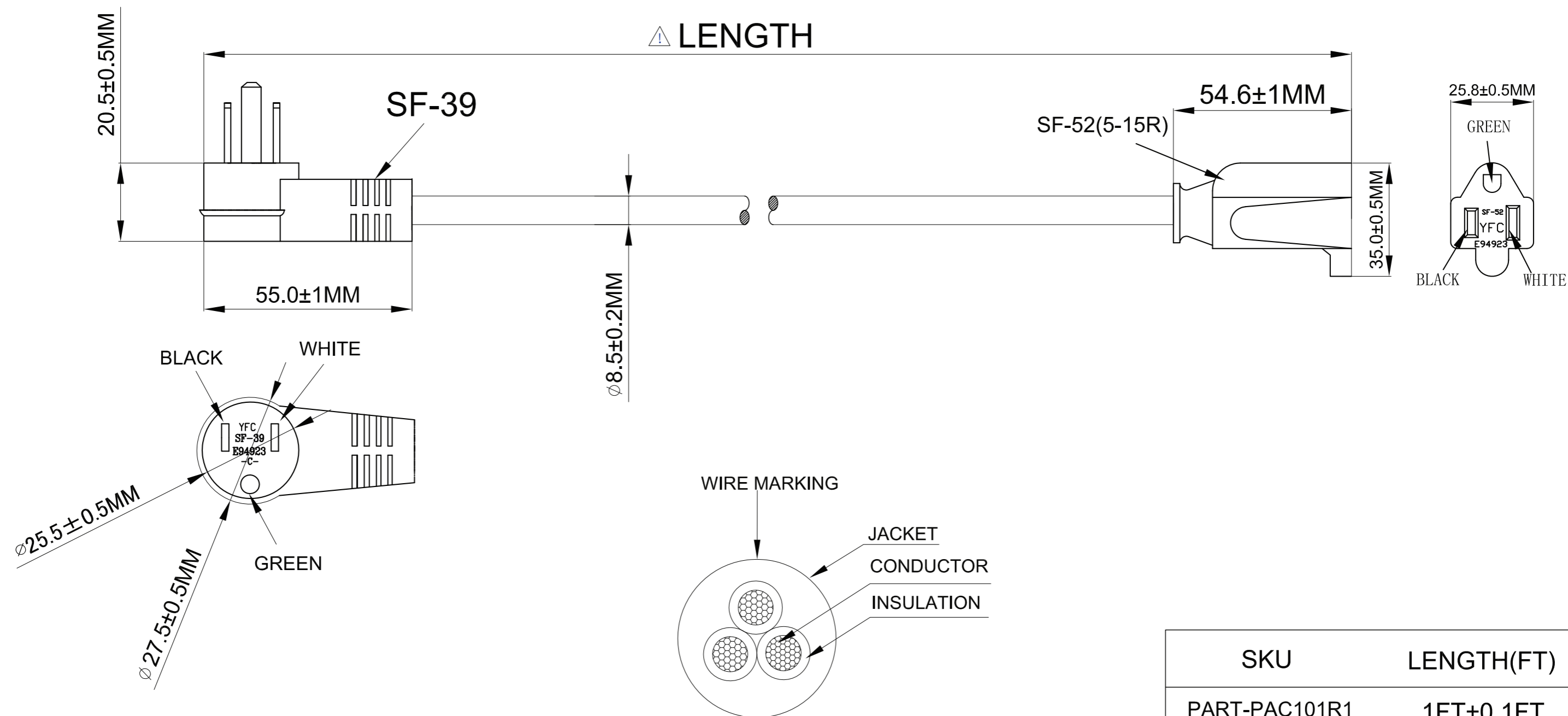

SKU	LENGTH(FT)
PART-PAC101R1	1FT \pm 0.1FT
PART-PAC101R3	3FT \pm 0.1FT

REMARKS:

- 1.PLUG(SF-39) RATED POWER:125V 13A
- 2.CONNECTOR(SF-52) RATED POWER:125V 13A
- 3.WIRE: SJT 3X16AWG 60°C RATED VOLTAGE:300V
- 4.DVW TEST:1500V,1S
- 5.POLARIZATION AND CONTINUITY TEST
- 6.COMPLY WITH UL817 IEC60320 STANDARD
- 7.COLOR: BLACK

WIRE MARKING
(Hollow)
NO.241

(UL) E135710-F3 SJT 3X16AWG 60°C 300V VW-1 c(UL) SJT 3X1.31mm²(16AWG) 60°C 300V FT2 YFC-BONEAGLE