


Computer Power Cord - AS/NZS 3112 to C13 - XX m

PXTA101XXM

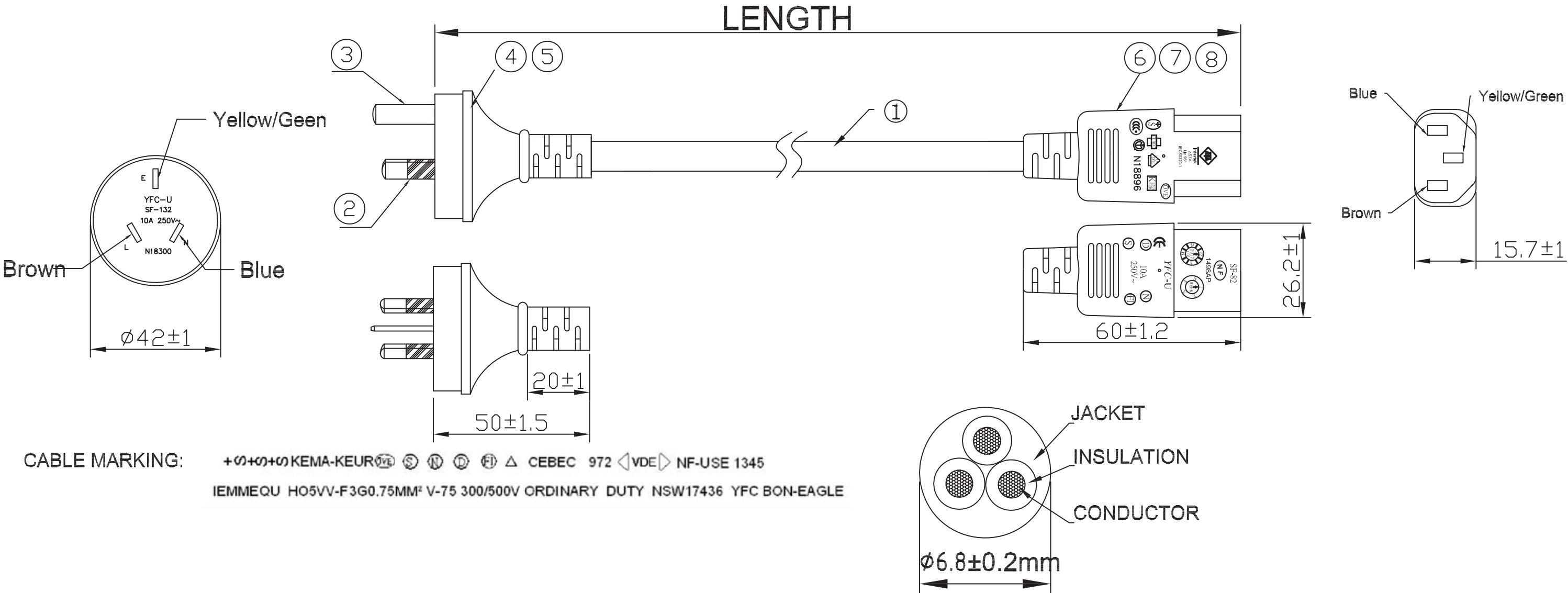

Electrical Performance (20°C)	
Item	Parameter
Conductor resistance	$\leq 26.0 \Omega / 1000 \text{m}$
Voltage Rating	AC 300V

SKU	Length (M)
PXTA1011M	1 M $\pm$ 3 0 m m
PXTA1012M	2 M $\pm$ 4 0 m m

8	Socket molding	Molding (SF-82) PVC	20.5 G
7	Inner BKT	IEC 320-C13 inner bracket	1 PCS
6	Connector	IEC 320-C13 connector female	3 PCS
5	Plug molding	Molding (SF-132) PVC	20 G
4	Inner BKT	SF-132 inner bracket	1 PCS
3	Connector	SF-132 connector, ground	1 PCS
2	Connector	SF-132 blade	2 PCS
1	Cable	HO5VV-F 3G 0.75mm2 BLACK	1 PCS
NO.	ITEM	REVISION	Q'TY