


Computer Power Cord - 2-Prong Plug with Ground Wire to C13 - 2 m

PXTJ1012M

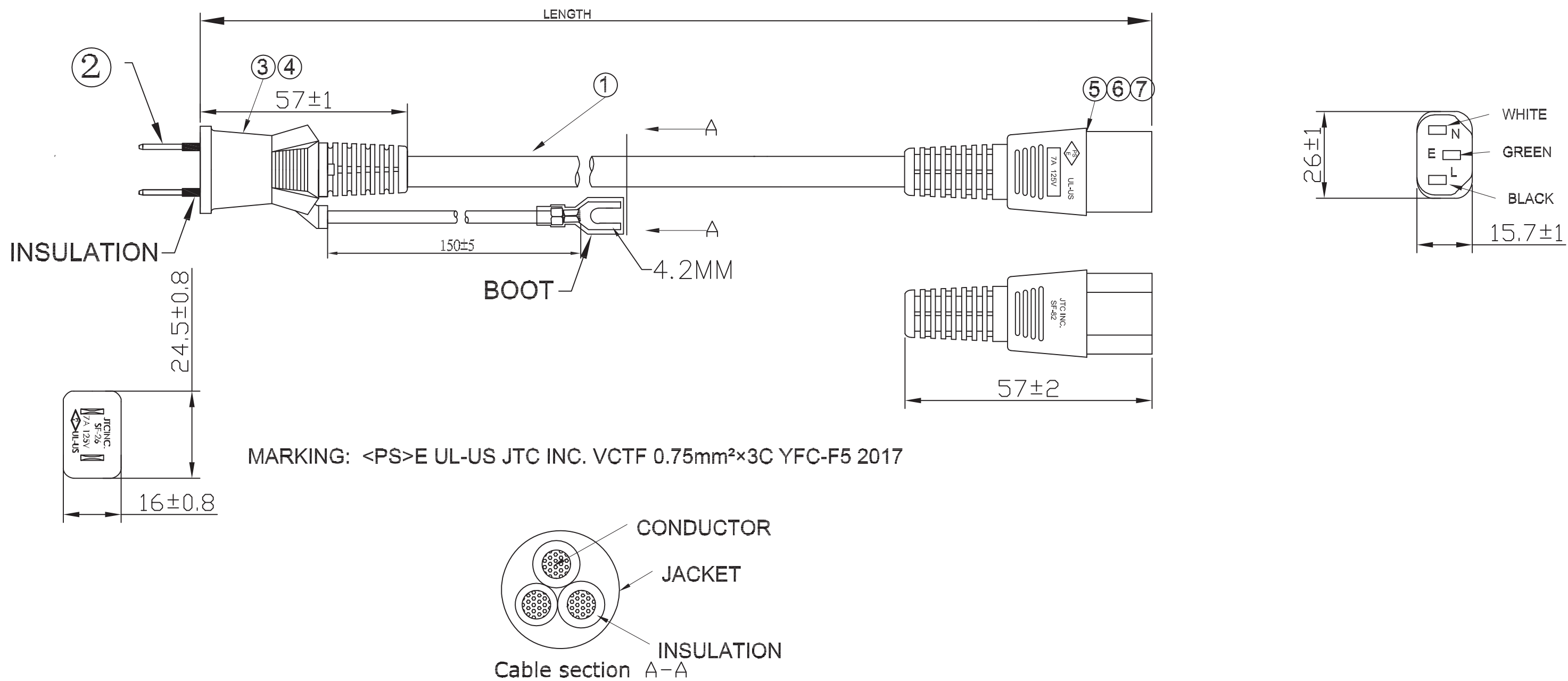

SKU	Length
PXTJ1011M	1 M ±3 0 m m
PXTJ1012M	2 M ±4 0 m m

Electrical Performance (20°C)	
Item	Parameter
Conductor resistance	≤26.0Ω/1000m
Voltage Rating	AC 300V

7	Socket molding	Molding (SF-82) PVC	24.3 G
6	Inner BKT	IEC 320-C13 inner bracket	1 PCS
5	Connector	IEC 320-C13 connector female	3 PCS
4	Plug molding	Molding (SF-26) PVC	25.5 G
3	Inner BKT	26 inner bracket	1 PCS
2	Connector	26 blade	2 PCS
1	Cable	VCTF 0.75mm²*3C BLACK	1 PCS
NO.	ITEM	REVISION	Q'TY