
 


ELECTRICAL TEST:
100% OPEN & SHORT & MIS WIRE TEST

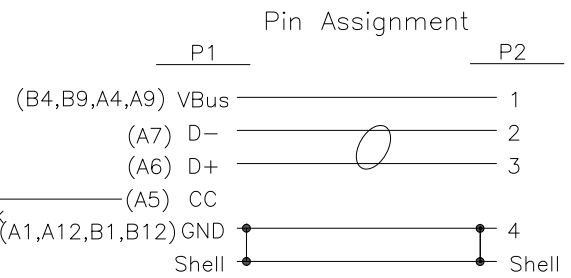

11	High temperature adhesive tape~W=5MM	0.24	m
10	W=5MM 25u~Double conductive copper foil	0.24	m
9	USB2.0 (B)M~Solder Type~Front Shell~Nickel Plated	1	pcs
8	USB2.0 (B)M~Solder Type~Back Shell~Nickel Plated	1	pcs
7	USB2.0 (B)M~Insulator:Black~Solder Type~Pin Gold plated	1	pcs
6	TYPE C~upper mater cover~Nickel Plated~T=0.15mm	1	pcs
5	TYPE C~lower mater cover~Nickel Plated~T=0.15mm	1	pcs
4	45P~Black PVC	16	g
3	Low pressure mold material	0.5	g
2	TYPEC~USB2.0 C Type Connector With~PCB~5.1K~Nickel Plated	1	pcs
1	NO~UL~22AWG(41/0.10TC+250DNylon)*1C+[30AWG(19/0.06TC)+A]*1P+3E(26/0.10TC)+AB(16/9/0.06TC 80%TC)OD:3.5MM~Black PVC	2.01	m
NO	DESCRIPTION	Q'TY	UNIT

THIRD ANGLE PROJECTION



GENERAL NOTES

DIMENSIONS ARE IN MM - DO NOT SCALE
THIS DOCUMENT CONTAINS CONFIDENTIAL, PROPRIETARY INFORMATION THAT IS PROPERTY OF STARTECH.COM



PRODUCT ID	USB2CB2M		
DESCRIPTION	USB-C to USB-B Cable - M/M - 2 m (6 ft.) - USB 2.0		
REV: A	DO NOT SCALE	SHEET : 1 OF: 1	DATE: 06/22/2020